


Aerospace & Defense

Ground Mobile Electronic Countermeasures

INPUT	28 Vdc
OUTPUT	Factory-configurable outputs from 3.3 – 48 Vdc
TOTAL POWER	Up to 800 Watts (80 A)
WEIGHT	1.78 lbs / 1.5 lbs
DIMENSIONS	6.68" x 4.55" x 0.82" / 6.69" x 3.62" x 0.76"
OPERATING TEMP.	-40°C to +85°C
COOLING	Low profile coldplate
COMPLIANCE	MIL-STD-810 (shock & vibration)

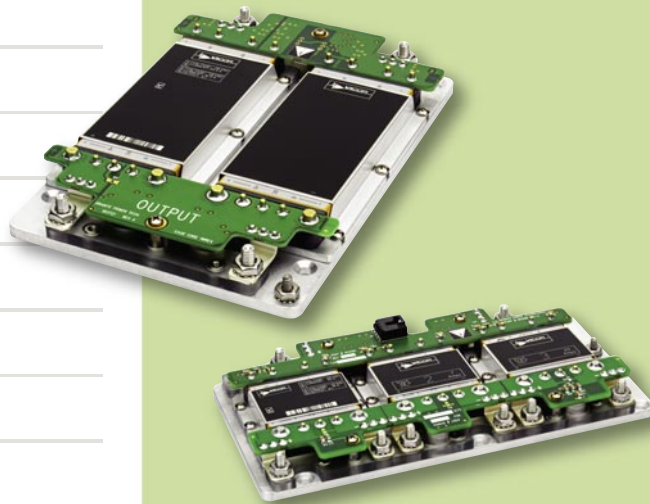

Highly flexible COTS family of DC-DC converters with low profile, coldplate mounting and rugged construction.




Granite Power Technologies
Manchester, NH
Tel: 603-623-3222
granitepower.com

cstmG_AD001

Aerospace & Defense

Ground to Air Missile

INPUT	28 Vdc
OUTPUT	<ul style="list-style-type: none">• 3.3 Vdc• 5 Vdc• 12 Vdc
TOTAL POWER	110 Watts
WEIGHT	2.25 lbs.
DIMENSIONS	7.5" x 4.0" x 1.5"
OPERATING TEMP.	-55°C to +100°C
COOLING	Conduction
COMPLIANCE	<ul style="list-style-type: none">• MIL-STD-810 (shock & vibration)• MIL-STD-461 (EM I)

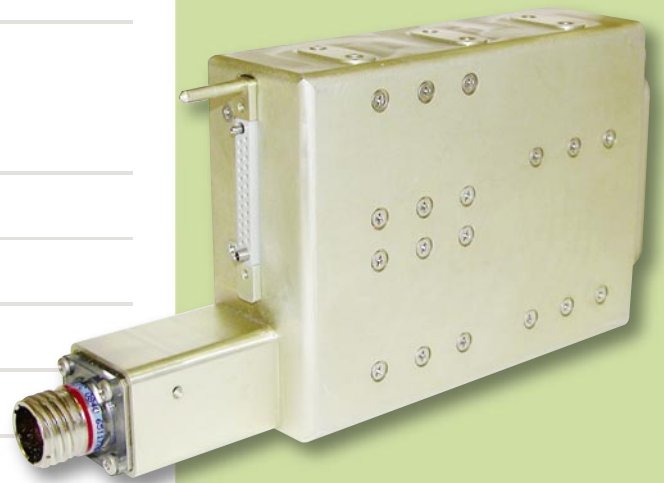

This 28 Vdc multi-output power supply is housed in a rugged enclosure able to withstand severe shock and vibration environments.

VICOR CUSTOM
GRANITE POWER

Granite Power Technologies
Manchester, NH
Tel: 603-623-3222
granitepower.com

cstmG_AD002